

HC-B 6-TFL-40/O1M20G

Order No.: 1604731

<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=1604731>

HEAVYCON sleeve housing B6, for single locking latch, height 40 mm,
with support 1x M20, straight conductor exit

Commercial data

GTIN (EAN)	4017918881078
sales group	D002
Pack	10 pcs.
Customs tariff	85389099
Weight/Piece	0.1129 KG
Catalog page information	Page 480 (PC-2009)

Product notes

WEEE/RoHS-compliant since:
03/01/2006



<http://www.download.phoenixcontact.com>
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

Technical data

General data

Note	For contact inserts HC-B6, BB10, DD24, M
Design	B6
Height	40 mm
Width	43 mm
Length	60 mm

Housing type	Sleeve housings
Locking type	for single locking latch
Cable exit	Straight
Type of the screw connection	1x M20
Degree of protection	IP65
Ambient temperature (operation)	-40 °C ... 125 °C
Housing material	Aluminum, die-cast
Housing surface material	Powder-coated, gray

Certificates / Approvals




Certification

GOST

Diagrams/Drawings

Dimensioned drawing

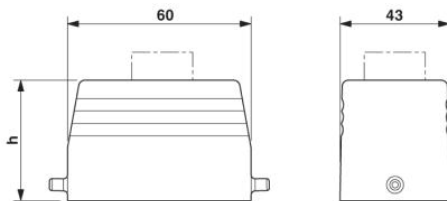

Address

PHOENIX CONTACT K.K.
Yusen Shinyokohama 1-chome Bldg. 6F
J-Yokohama 222-0033, Japan
Phone +81/45/471-0030
Fax +81/45/471-0031
<http://www.phoenixcontact.co.jp>



© 2010 Phoenix Contact
Technical modifications reserved;