


VS-04-BUB-FK-F/IP67

Order No.: 1653867

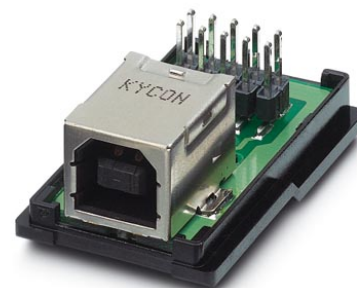

<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=1653867>

USB socket insert, 4-pos., socket USB type B on flat-ribbon cable terminal strip, pitch 2.54, for the Freenet system in the panel mounting frame, IP20 terminal outlet, 19" patch panel and service interface

Commercial data

GTIN (EAN)	4017918970192
Note	Made-to-order
sales group	D531
Pack	1 pcs.
Customs tariff	85366990
Weight/Piece	0.0156 KG
Catalog page information	Page 310 (PC-2009)

Product notes

WEEE/RoHS-compliant since:
09/20/2006



<http://www.download.phoenixcontact.com>
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

Technical data

Mechanical characteristics

Number of positions	4
Insertion/withdrawal cycles	≥ 1000
Type of connection	Flat-ribbon cable connection, pitch 2.54 mm
Ambient temperature (operation)	-15 °C ... 65 °C

Material data

Inflammability class acc. to UL 94	V0
Housing material	PC
Contact carrier material	Thermoplastic
Contact material	Copper alloy
Contact surface material	Gold over nickel
Degree of protection	IP20


Electrical characteristics

Rated voltage (III/3)	30 V
Rated current	1 A
Insulation resistance	$\geq 1 \text{ G}\Omega$
Transmission characteristics (category)	USB 2.0

Diagrams/Drawings

Schematic diagram

Pin	USB B
1	GND
2	
3	Shield
4	
5	D+
6	D-
7	Shield
8	
9	VBUS
10	

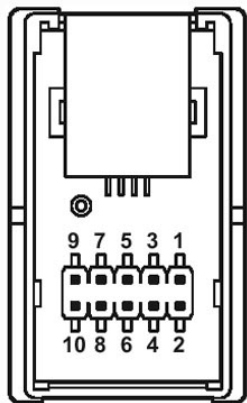

Contact assignment

Address

PHOENIX CONTACT K.K.
Yusen Shinyokohama 1-chome Bldg. 6F
J-Yokohama 222-0033, Japan
Phone +81/45/471-0030
Fax +81/45/471-0031
<http://www.phoenixcontact.co.jp>



© 2010 Phoenix Contact
Technical modifications reserved;