


VS-06-BU-BU-F/IP67

Order No.: 1654329

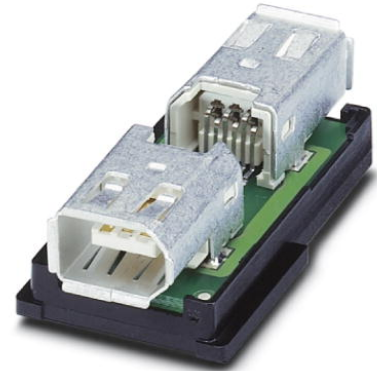

<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=1654329>

FireWire socket insert, 6-pos., socket on socket, for the Freenet system in the panel mounting frame, IP20 terminal outlet, 19" patch panel and service interface

Commercial data	
GTIN (EAN)	4017918970604
Note	Made-to-order
sales group	D541
Pack	1 pcs.
Customs tariff	85366990
Weight/Piece	0.0173 KG
Catalog page information	Page 312 (PC-2009)

Product notes

WEEE/RoHS-compliant since:
09/20/2006



<http://www.download.phoenixcontact.com>
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

Technical data

Mechanical characteristics	
Number of positions	6
Insertion/withdrawal cycles	≥ 1000
Type of connection	Socket
Ambient temperature (operation)	-15 °C ... 65 °C

Material data


Inflammability class acc. to UL 94	V0
Housing material	PC
Contact carrier material	PBT-GF
Contact material	Copper alloy
Contact surface material	Gold over nickel
Degree of protection	IP20

Electrical characteristics

Rated voltage (III/3)	30 V
Rated current	1 A
Insulation resistance	$\geq 1 \text{ G}\Omega$
Transmission characteristics (category)	FireWire (400 Mbps)

Diagrams/Drawings

Dimensioned drawing

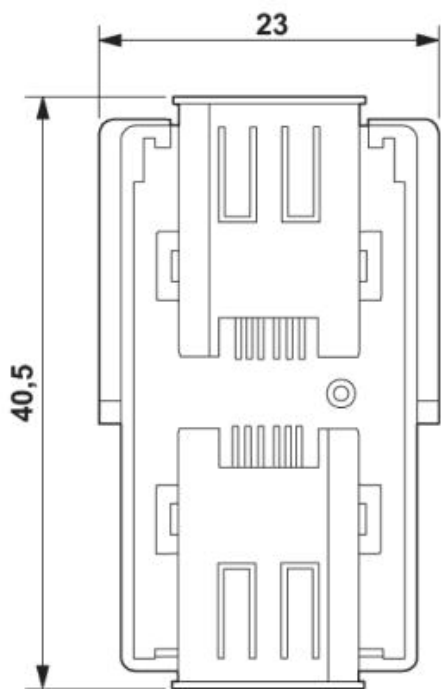

FireWire female insert, socket/socket

Address

PHOENIX CONTACT Ltd.
235 Watline Ave.
Mississauga, Ontario L4Z 1P3, Canada
Phone (905) 890-2820
Fax (905) 890-0180
<http://www.phoenixcontact.ca>



© 2010 Phoenix Contact
Technical modifications reserved;