

HC-DS 29 Z

Order No.: 1772654



<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=1772654>

Pressure screws, with strain relief clamps, nickel-plated brass,
clamping area 19 mm ... 27 mm, Pg type 29

Commercial data

EAN	4017918037314
Pack	10 pcs.
Customs tariff	74153300
Weight/Piece	0.0925 KG
Catalog page information	Page 525 (PC-2009)

Product notes

WEEE/RoHS-compliant since:
04/10/2006



<http://www.download.phoenixcontact.com>
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

Technical data

General data

Material, pressure screw	Nickel-plated brass
Wrench size, union nut	42 mm
Thread type on connection side	Pg29
Clamping range of the strain relief clip	19.00 mm ... 27.00 mm

Certificates / Approvals




Certification

GOST

Diagrams/Drawings

Dimensioned drawing

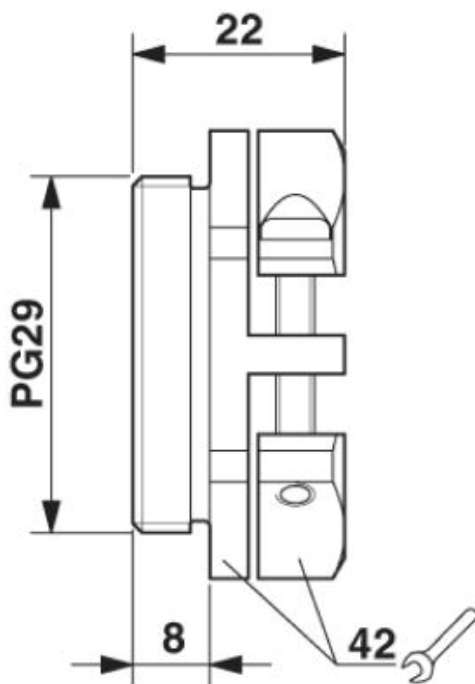

Address

PHOENIX CONTACT Inc., USA
586 Fulling Mill Road
Middletown, PA 17057, USA
Phone (800) 888-7388
Fax (717) 944-1625
<http://www.phoenixcon.com>



© 2010 Phoenix Contact
Technical modifications reserved;